
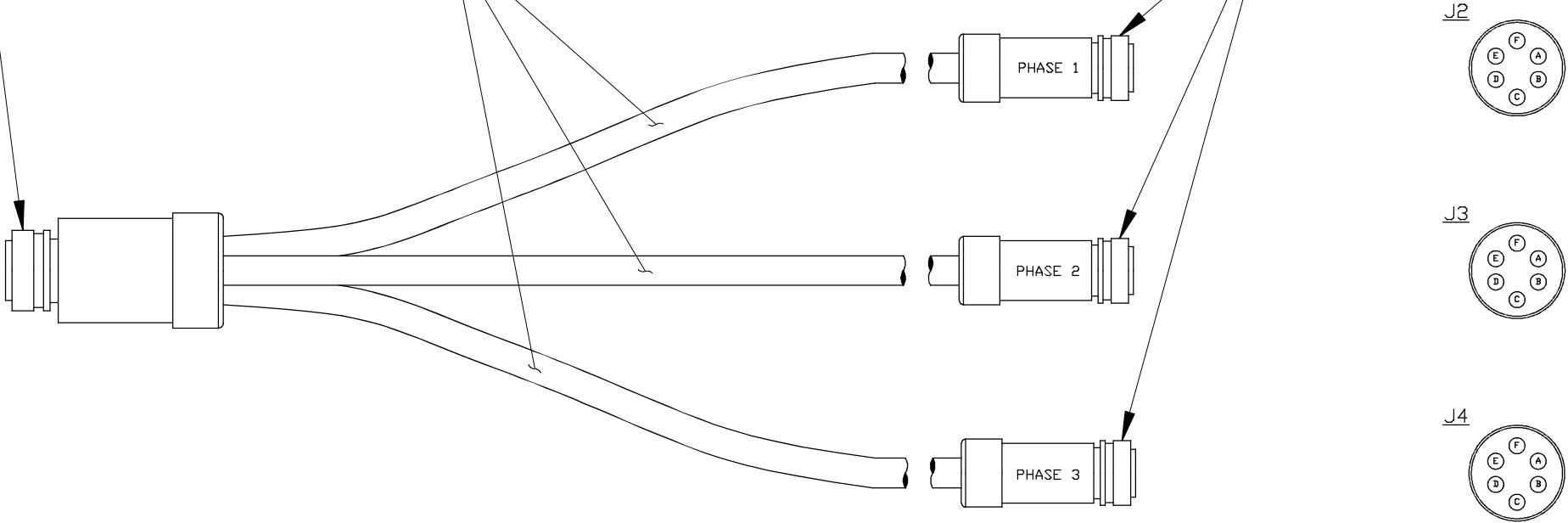


- MILITARY STANDARD
- 3106 STYLE
- INSERT ARRANGEMENT 22-14S
- SOLID BACKSHELL
- MAX DIAMETER 1.468 IN.

- JACKET:
- SOOW CABLE
 - 6 CONDUCTOR, 16 AWG
 - TEMPERATURE RANGE: -40°C TO 90°C
- INDUSTRY APPROVALS:
- UL FLEXIBLE CORD UL SUBJECT 62
 - CSA FLEXIBLE CORD C22.2-49
 - MSHA APPROVED
 - ROHS COMPLIANT

- MILITARY STANDARD
- 3106 STYLE
- INSERT ARRANGEMENT 18-12S
- SOLID BACKSHELL
- MAX DIAMETER 1.22 IN.

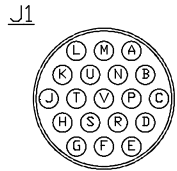

CONNECTOR PIN	WIRE COLOR	WIRE TYPE	FUNCTION		CONNECTOR PIN
J1-U	RED	#16 AWG 26/30 STRAND	PHASE 1		J2-A
J1-E	WHITE	#16 AWG 26/30 STRAND			J2-B
J1-D	GREEN	#16 AWG 26/30 STRAND			J2-C
J1-C	BLACK	#16 AWG 26/30 STRAND			J2-D
J1-N	ORANGE	#16 AWG 26/30 STRAND			J2-E
J1-M	BLUE	#16 AWG 26/30 STRAND			J2-F
J1-U	RED	#16 AWG 26/30 STRAND	PHASE 2		J3-A
J1-H	WHITE	#16 AWG 26/30 STRAND			J3-B
J1-G	GREEN	#16 AWG 26/30 STRAND			J3-C
J1-F	BLACK	#16 AWG 26/30 STRAND			J3-D
J1-R	ORANGE	#16 AWG 26/30 STRAND			J3-E
J1-P	BLUE	#16 AWG 26/30 STRAND			J3-F
J1-U	RED	#16 AWG 26/30 STRAND	PHASE 3		J4-A
J1-L	WHITE	#16 AWG 26/30 STRAND			J4-B
J1-K	GREEN	#16 AWG 26/30 STRAND			J4-C
J1-J	BLACK	#16 AWG 26/30 STRAND			J4-D
J1-T	ORANGE	#16 AWG 26/30 STRAND			J4-E
J1-S	BLUE	#16 AWG 26/30 STRAND			J4-F